


Instructions


FD



FD

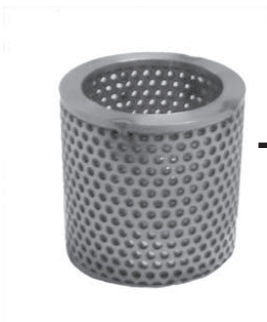

VFGS
DN 15 - 125

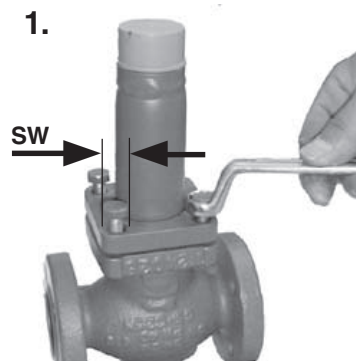

7.

	Nm	SW
DN 15 / 20	35	16
DN 25 / 32	60	18
DN 40 / 50	100	24
DN 65 / 60	130	24
DN 100 / 125	200	30

